

OBO Quick series

Arrangeable cable and pipe clips – available with stagelessly adjustable clamping range or safety lock



Quick clip The high-speed clip

- Extreme loading capacity
- Insertion slopes
- Slot fastening
- Stackable among each other
- Latch-in hole/middle stopper



Multi-Quick clip

- One clip for multiple dimensions
- Universally applicable
- PG and metric

starQuick clip

- Snap lock with patented safety system
- All sizes clip together, up to size SQ28
- UV-proof and weatherproof polyamide
- Wall and ceiling mounting


OBO Quick series

The OBO Quick series offers three different types of halogen-free pressure and pipe clips for time-saving and secure fastening of cables and electrical installation pipes. Benefit from short mounting times when fastening installations on walls and ceilings, both indoors and outdoors.

All the clip types and sizes of the OBO Quick series can be interconnected easily, thanks to the shared arrangement contour. This means you can mount up to three clips with a single drill hole. The patented shape of the arrangement contour permits a particularly high carrying capacity.



G	A	B	C	D	E	F	H	H	F (20 °C)
	mm	mm	mm	mm	mm	mm	mm	mm	N
M16	25.3	16	11.5	15.5	7	4.2	25	10	75
M20	30.3	16	14	19.4	9	4.2	29.5	10	90
M25	36.3	16	17.5	24.3	12	4.2	34	10	100
M32	46.3	16	22.4	31.4	12	4.2	42	11	120
M40	57.3	16	26	39.2	11	4.6	51	12	140
M50	70.3	18	32	49	12	6	63	14	165
M63	87.3	20	43	61.5	12	6	74.5	15	230

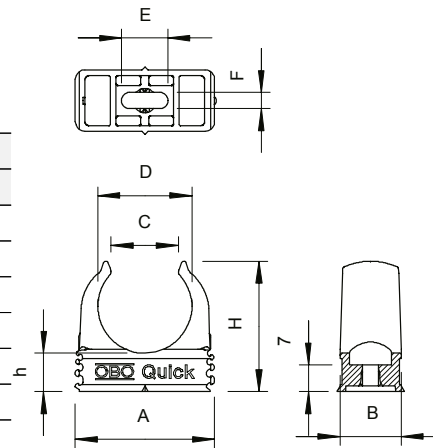

Quick clip, light grey



Type	Nominal size	Colour	Pack. pcs	Weight kg/100 pcs.	Item No.
2955 M16	M16	Light grey	100	0.252	2149 00 4
2955 M20	M20	Light grey	100	0.325	2149 01 0
2955 M25	M25	Light grey	100	0.433	2149 01 6
2955 M32	M32	Light grey	50	0.630	2149 02 2
2955 M40	M40	Light grey	50	0.835	2149 02 8
2955 M50	M50	Light grey	25	1.454	2149 03 4
2955 M63	M63	Light grey	20	2.203	2149 04 0

PP Polypropylene

/100 pcs.

OBO Bettermann GmbH & Co. KG
 PO Box 1120
 58694 Menden

www.obo-bettermann.com

Customer Service Germany
 Tel. +49 (0)2373 89-1700
 Fax +49 (0)2373 89-1238
 E-mail: export@obo.de

