

## Flat cable threaded connection, metric thread M25




Flat-cable entry, choke-nipple design with metric connecting thread to IEC 432, protection rating IP31, with pre-mounted support sealing ring 107/F.

Type	Thread	Flat cables/ thickness mm	Flat cables/ width mm	Colour	Pack. pcs	Weight kg/100 pcs.	Item No.
106 FL M25 6 30	M25	4-6	27-30	Stone grey	25	2,630	2013006
106 FL M25 8 33	M25	6-8	30-33	Stone grey	25	2,630	2013007
106 FL M25 9 22	M25	7-9	19-22	Stone grey	25	2,630	2013008
106 FL M25 9 39	M25	7-9	36-39	Stone grey	25	2,630	2013009
106 FL M25 10 29	M25	8-10	26-29	Stone grey	25	2,630	2013010
106 FL M25 10 31	M25	8,5-10,5	28,5-31,5	Stone grey	25	2,630	2013011
106 FL M25 12 35	M25	9-12	31-35	Stone grey	25	2,630	2013012
106 FL M25 14 40	M25	11-14	37-40	Stone grey	25	2,680	2013013
106 FL M32 6 30	M32	4-6	27-30	Stone grey	15	3,450	2013015
106 FL M32 8 33	M32	6-8	30-33	Stone grey	15	3,450	2013016
106 FL M32 9 22	M32	7-9	19-22	Stone grey	15	3,450	2013017
106 FL M32 9 39	M32	7-9	36-39	Stone grey	15	3,450	2013018
106 FL M32 10 29	M32	8-10	26-29	Stone grey	15	3,450	2013019
106 FL M32 10 31	M32	8,5-10,5	28,5-31,5	Stone grey	15	3,450	2013020
106 FL M32 12 35	M32	9-12	31-35	Stone grey	15	3,450	2013021
106 FL M32 14 40	M32	11-14	37-40	Stone grey	15	3,500	2013022

PE Polyethylene

### Dimensions

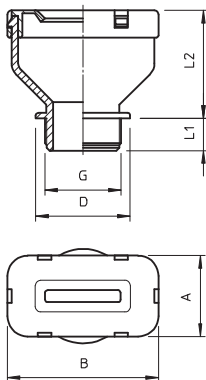

### Important dimensions, flat cable threaded connection

G	D	L1	L2	A	B
	mm	mm	mm	mm	mm
M25	35	12	40	30	56