

Flat cable threaded connection, PG thread




Flat-cable entry, choke-nipple design with PG connecting thread to DIN 40430, protection rating IP31, with pre-mounted support sealing ring 107/F.

Type	Thread	Flat cables/ thickness mm	Flat cables/ width mm	Colour	Pack. pcs	Weight kg/100 pcs.	Item No.
106 FL 21 6 30	Pg 21	4-6	27-30	Stone grey	25	2,006	2012855
106 FL 21 8 33	Pg 21	6-8	30-33	Stone grey	25	1,977	2012782
106 FL 21 9 22	Pg 21	7-9	19-22	Stone grey	25	1,996	2012820
106 FL 21 9 39	Pg 21	7-9	36-39	Stone grey	25	1,975	2012804
106 FL 21 10 29	Pg 21	8-10	26-29	Stone grey	25	1,989	2012839
106 FL 21 10 31	Pg 21	8,5-10,5	28,5-31,5	Stone grey	25	1,999	2012871
106 FL 21 12 35	Pg 21	9-12	31-35	Stone grey	25	1,965	2012847
106 FL 21 14 40	Pg 21	11-14	37-40	Stone grey	25	2,015	2012928
106 FL 29 14 40	Pg 29	11-14	37-40	Stone grey	15	3,500	2012774

PE Polyethylene

Dimensions

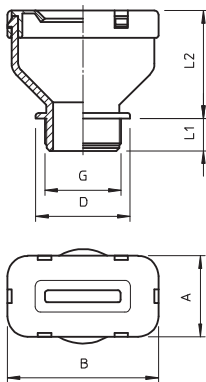

Important dimensions, flat cable threaded connection

G	D	L1	L2	A	B
	mm	mm	mm	mm	mm
PG21	35	12	40	30	56
PG 29	46	13	46	30	56